

95C Frostproof Sillcock 180° Turn

APPLICATIONS

- Frostproof sillcock for use in low pressure residential and commercial water systems

MATERIALS & CONSTRUCTION

- Ceramic closure seats promote a long trouble-free life
- "Flow Wedge" handle for easy visual indication of flow volume
- "Self-draining" feature allows water to drain from sillcock to prevent freezing (when water is off and hose is removed)
- Lockshield that restricts operation when handwheel is removed
- Chrome plated body
- Wide mounting flange
- Internal backflow device
- Epoxy-coated ergonomic aluminum handwheel
- Multiple end connections and tube lengths available
 - Solder, Threaded, PEX
 - 4", 6", 8", 10", 12", 14"
- 2 Repair kits Available
 - RG5000H Replacement Seat Cartridge and Vent
 - RG5000K Replacement Handwheel & Siding Wedge

DESIGN CRITERIA

- NSF/ANSI 61-9 Approved
- ASSE 1019-C
- CAN/CSA-B64.2.1


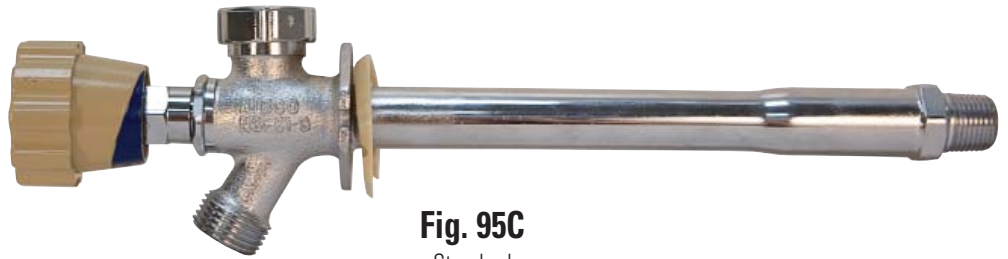


Fig. 95C
Standard



Also available with Pex connection (95CPEX)

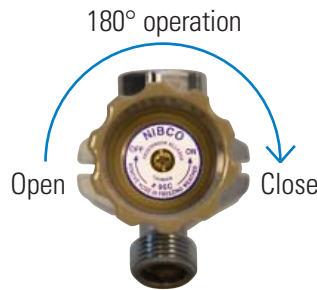

BENEFITS:



The ceramic seats provide positive control that are not prone to damage during closing by over-tightening like the traditional plunger style.



The metal handwheel is made of epoxy-coated aluminum. The design provides an ergonomic comfort grip. The "Flow Wedge" feature allows for easy visual indication of flow volume.

Fig. 95C Frostproof Sillcock

Chrome Plated Brass Body • 180° Turn • Ceramic Seats •
Built in Lockshield • Flow Indicator on Metal Handwheel

CONFORMS TO • CAN/CSA B64.2.1 • ASSE 1019-C • NSF/ANSI 61-9

MATERIAL LIST

PART	SPECIFICATION
1. Handwheel	Aluminum B85 Epoxy Coated
2. ID Plate	Aluminum
3. Screw	Brass B16 C36000
4. Bonnet	Brass B16 C36000
5. O-Ring	NBR
6. Lockshield	Brass B16 C36000
7. Washer Seal	NBR
8. Stem	Brass B135 C33000
9. Screw	304 SS
10. V-Clip	304 SS
11. V-Cup Seal	NBR
12. Housing	Brass B16 C36000
13. O-Ring	NBR
14. Seal Washer	TFE
15. Inner Stem	Brass B16 C36000
16. Seat 180°	Ceramic
17. Movement 180°	Ceramic
18. Washer	Silicon Rubber
19. Washer	Brass B16 C36000
20. Spring Check Valve	304 SS
21. Valve Base	Brass B16 C36000
22. O-Ring	Viton
23. Cast Body	Brass B584 C85700
24. Vent Cap	POM - Chrome Plated
25. Vent Body	POM
26. Poppet	POM
27. Vent Seat	NBR
28. Inlet End	Brass B16 C36000
29. Body Tube	Brass B135 C33000
30. Siding Plate	Plastic
31. O-Ring	NBR



DIMENSIONS — WEIGHTS

Size (In.)	A	B	Wt. Lbs.	Size (In.)	A	B	Wt. Lbs.
1/2 x 4	9 3/4	4	1.28	3/4 x 4	9 3/4	4	1.31
1/2 x 6	11 3/4	6	1.37	3/4 x 6	11 3/4	6	1.40
1/2 x 8	13 3/4	8	1.44	3/4 x 8	13 3/4	8	1.47
1/2 x 10	15 3/4	10	1.49	3/4 x 10	15 3/4	10	1.52
1/2 x 12	17 3/4	12	1.54	3/4 x 12	17 3/4	12	1.62
1/2 x 14	19 3/4	14	1.60	3/4 x 14	19 3/4	14	1.64

