

BRONZE & IRON
Y-STRAINERS

STR-0621

Effective June 14, 2021 • Supersedes STR-0321 of March 22, 2021



List Prices subject to change without notice
Visit our website for the most current information.

BRONZE Y-STRAINER — SOLDER END W/PLUG

Fig. No.	Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
S-221-A Class 125 20 Mesh Screen w/Plug	List Price	N/A	N/A	\$ 78.78	\$ 93.82	\$ 131.30	\$ 191.50	\$ 220.60	\$ 356.40	N/A	N/A
	Box Qty	—	—	10	5	5	2	2	2	—	—
	Unit Wgt.	—	—	.57	1.01	1.59	2.68	3.99	6.94	—	—
	Case Qty.	—	—	50	30	25	10	10	6	—	—
	UPC 039923-	—	—	279927	279934	279941	279958	279965	279972	—	—
S-222-A Class 125 Perforated Stainless Steel w/Plug	List Price	N/A	N/A	\$ 90.06	\$ 105.00	\$ 142.50	\$ 213.30	\$ 242.40	\$ 395.20	N/A	N/A
	Box Qty	—	—	10	5	5	2	2	2	—	—
	Unit Wgt.	—	—	.57	1.01	1.59	2.68	3.99	6.94	—	—
	Case Qty.	—	—	50	30	25	10	10	6	—	—
	UPC 039923-	—	—	280091	280107	280169	280176	280183	280190	—	—



BRONZE Y-STRAINER — SOLDER END W/SOLID CAP

Fig. No.	Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
S-221-B Class 125 20 Mesh Screen w/Solid Cap	List Price	N/A	N/A	\$ 78.78	\$ 93.82	\$ 132.40	\$ 189.00	\$ 219.40	\$ 353.80	N/A	N/A
	Box Qty	—	—	10	5	5	2	2	2	—	—
	Unit Wgt.	—	—	.57	1.01	1.59	2.68	3.99	6.94	—	—
	Case Qty.	—	—	50	30	25	10	10	6	—	—
	UPC 039923-	—	—	279989	279996	280008	280060	280077	280084	—	—
S-222-B Class 125 Perforated Stainless Steel w/Solid Cap	List Price	N/A	N/A	\$ 85.09	\$ 100.00	\$ 140.10	\$ 207.20	\$ 233.90	\$ 384.10	N/A	N/A
	Box Qty	—	—	10	5	5	2	2	2	—	—
	Unit Wgt.	—	—	.57	1.01	1.59	2.68	3.99	6.94	—	—
	Case Qty.	—	—	50	30	25	10	10	6	—	—
	UPC 039923-	—	—	280206	280213	280251	280268	280275	280282	—	—



BRONZE Y-STRAINER — THREADED END W/ PLUG

Fig. No.	Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
T-221-A Class 125 20 Mesh Screen w/Plug	List Price	\$ 76.24	\$ 76.24	\$ 76.24	\$ 103.80	\$ 132.40	\$ 185.00	\$ 221.80	\$ 381.70	\$ 831.00	\$ 1,134.00
	Box Qty	10	10	10	5	5	2	2	2	1	1
	Unit Wgt.	.74	.71	.81	1.13	1.85	2.96	4.47	7.45	14.94	21.96
	Case Qty.	50	50	50	30	25	10	10	6	3	2
	UPC 039923-	280299	280305	280312	280350	280367	280374	280381	280398	280442	280459
T-222-A Class 125 Perforated Stainless Steel w/Plug	List Price	\$ 78.78	\$ 78.78	\$ 78.78	\$ 111.30	\$ 141.20	\$ 200.00	\$ 235.10	\$ 408.50	\$ 889.00	\$ 1,215.00
	Box Qty	10	10	10	5	5	2	2	2	1	1
	Unit Wgt.	.74	.71	.81	1.13	1.85	2.96	4.47	7.45	14.94	21.68
	Case Qty.	50	50	50	30	25	10	10	6	3	2
	UPC 039923-	280619	280626	280633	280640	280657	280664	280671	280688	280695	280701

WARNING: Cancer and Reproductive Harm – www.P65Warnings.ca.gov.

NIBCO
AHEAD OF THE FLOW®


NIBCO INC.
WORLD HEADQUARTERS
WEB: www.nibco.com

1516 MIDDLEBURY STREET
ELKHART, IN 46516-4740
USA

DOMESTIC CUSTOMER SERVICE
PHONE: 800.234.0227
FAX: 800.234.0557

TECHNICAL SERVICE
PHONE: 888.446.4226
FAX: 888.336.4226

INTERNATIONAL OFFICE
PHONE: +1/574.295.3327
FAX: +1/574.295.3455

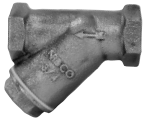

BRONZE Y-STRAINER — THREADED END W/SOLID CAP

Fig. No.	Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
T-221-B Class 125 20 Mesh Screen w/Solid Cap	List Price	\$ 72.48	\$ 72.48	\$ 72.48	\$ 100.00	\$ 131.30	\$ 182.70	\$ 219.40	\$ 376.90	\$ 823.00	\$ 1,123.00
	Box Qty	10	10	10	5	5	2	2	2	1	1
	Unit Wgt.	.74	.71	.81	1.13	1.85	2.96	4.47	7.45	14.94	21.68
	Case Qty.	50	50	50	30	25	10	10	6	3	2
	UPC 039923-	280466	280473	280480	280497	280541	280558	280565	280572	280596	280602

Fig. No.	Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
T-222-B Class 125 Perforated Stainless Steel w/Solid Cap	List Price	\$ 76.24	\$ 76.24	\$ 76.24	\$ 107.60	\$ 134.90	\$ 191.50	\$ 226.60	\$ 391.50	\$ 856.00	\$ 1,162.00
	Box Qty	10	10	10	5	5	2	2	2	1	1
	Unit Wgt.	.74	.71	.81	1.13	1.85	2.96	4.47	7.45	14.94	21.68
	Case Qty.	50	50	50	30	25	10	10	6	3	2
	UPC 039923-	280848	280855	280862	280879	280886	280893	280909	281029	281036	281043



IRON Y-STRAINER — THREADED END

Fig. No.	Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
T-751-A Class 250 20 Mesh Screen w/Plug	List Price	\$ 29.94	\$ 29.94	\$ 29.94	\$ 44.13	\$ 58.31	\$ 75.75	\$ 104.70	\$ 159.90	\$ 317.50	\$ 436.40
	Unit Wgt.	1.39	1.39	1.39	2.20	3.08	5.06	7.70	12.54	24.42	29.26
	Case Qty.	10	10	10	10	8	6	4	3	1	1
	UPC 039923-	308498	308511	308535	308559	308573	308580	308597	308610	308634	308658



IRON Y-STRAINER — FLANGED

Fig. No.	Size	2"	2 1/2"	3"	4"	5"	6"	8"	10"	12"
F-721-A Class 125 Perforated Screen w/Plug	List Price	\$ 330.80	\$ 360.00	\$ 421.80	\$ 639.00	\$ 1,164.00	\$ 1,444.00	\$ 2,554.00	\$ 4,731.00	\$ 6,752.00
	Unit Wgt.	18.04	32.56	37.84	67.10	94.60	136.62	270.60	374	605
	Case Qty.	1	1	1	1	1	1	1	1	1
	UPC 039923-	308672	308696	308702	308719	308733	308757	308771	308795	308801




IRON Y-STRAINER — FLANGED

Fig. No.	Size	14"	16"
F-721-A Class 125 Perforated Screen w/Plug	List Price	\$ 14,643.00	\$ 20,633.00
	Box Qty	10	10
	Unit Wgt.	863	1380
	Case Qty.	1	1
	UPC 039923-	310415	310422

WARNING: Cancer and Reproductive Harm – www.P65Warnings.ca.gov.

 BRONZE REPLACEMENT PARTS



20 Mesh Screens

Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
List Price	\$ 23.15	\$ 23.15	\$ 23.15	\$ 23.15	\$ 27.65	\$ 33.82	\$ 38.41	\$ 66.30	\$ 29.34	\$ 58.41
Part Number	T066957PP	T066957PP	T066957PP	T066958PP	T066959PP	T066960PP	T066961PP	T066962PP	T066963PP	T066964PP



Perforated Stainless Steel Screens

Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
List Price	\$ 23.15	\$ 23.15	\$ 23.15	\$ 21.57	\$ 26.66	\$ 26.18	\$ 32.23	\$ 41.57	\$ 58.41	\$ 77.57
Part Number	T066997PP	T066997PP	T066997PP	T066998PP	T066999PP	T067000PP	T067001PP	T067002PP	T067003PP	T067004PP

PTFE Bonnet Gasket

Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
List Price	\$ 0.97	\$ 0.97	\$ 0.97	\$ 0.97	\$ 2.31	\$ 2.90	\$ 3.63	\$ 4.37	\$ 9.94	\$ 17.10
Part Number	T066965PP	T066965PP	T066965PP	T066966PP	T066967PP	T066968PP	T066969PP	T066970PP	T066971PP	T066972PP

NPT Plug

Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
List Price	\$ 2.31	\$ 2.31	\$ 2.31	\$ 2.31	\$ 3.27	\$ 6.66	\$ 6.66	\$ 6.79	\$ 15.03	\$ 24.72
Part Number	T067044PP	T067044PP	T067044PP	T067045PP	T067045PP	E177050FC	E177050FC	E177100FC	E177150FC	E177200FC

⚠ **WARNING:** Cancer and Reproductive Harm – www.P65Warnings.ca.gov.

IRON REPLACEMENT PARTS



T-751-A — 20 Mesh (1/4" - 2"), 1/16" Perforated (2 1/2" - 3") Stainless Steel Screens

Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
List Price	\$ 4.37	\$ 4.37	\$ 4.37	\$ 5.82	\$ 5.82	\$ 5.82	\$ 7.28	\$ 8.61	\$ 48.36	\$ 64.00
Part Number	RG60009	RG60010	RG60011	RG60012	RG60013	RG60014	RG60015	RG60016	RG60017	RG60018



F-721-A — 1/16" Perforated (2" - 4"), 1/8" Perforated (5" - 16") Stainless Steel Screens

Size	2"	2 1/2"	3"	4"	5"	6"	8"	10"	12"	14"	16"
List Price	\$ 38.54	\$ 49.82	\$ 56.97	\$ 89.58	\$ 176.40	\$ 289.70	\$ 421.80	\$ 612.00	\$ 884.00	\$ 1,391.00	\$ 1,919.00
Part Number	RG60019	RG60020	RG60021	RG60022	RG60023	RG60024	RG60025	RG60026	RG60027	RG60028	RG60029

T-751-A — Metal-Filled Graphite Bonnet Gasket

Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
List Price	\$ 4.37	\$ 4.37	\$ 4.37	\$ 4.37	\$ 4.37	\$ 5.82	\$ 5.82	\$ 7.28	\$ 10.06	\$ 10.06
Part Number	RG60030	RG60031	RG60032	RG60033	RG60034	RG60035	RG60036	RG60037	RG60038	RG60039

F-721-A — Metal-Filled Graphite Bonnet Gasket

Size	2"	2 1/2"	3"	4"	5"	6"	8"	10"	12"
List Price	\$ 8.61	\$ 10.06	\$ 11.51	\$ 14.43	\$ 20.00	\$ 28.61	\$ 31.28	\$ 35.64	\$ 45.45
Part Number	RG60040	RG60041	RG60042	RG60043	RG60044	RG60045	RG60046	RG60047	RG60048

T-751-A — Iron NPT Plug

Size	1/4"	3/8"	1/2"	3/4"	1"	1 1/4"	1 1/2"	2"	2 1/2"	3"
List Price	\$ 7.28	\$ 7.28	\$ 7.28	\$ 7.28	\$ 7.28	\$ 8.61	\$ 8.61	\$ 10.06	\$ 10.06	\$ 15.75
Part Number	RG60001	RG60001	RG60001	RG60002	RG60002	RG60004	RG60004	RG60005	RG60005	RG60006

F-721-A — Iron NPT Plug

Size	2"	2 1/2"	3"	4"	5"	6"	8"	10"	12"
List Price	\$ 7.28	\$ 10.06	\$ 10.06	\$ 17.10	\$ 24.24	\$ 24.24	\$ 24.24	\$ 24.24	\$ 24.24
Part Number	RG60003	RG60005	RG60005	RG60007	RG60008	RG60008	RG60008	RG60008	RG60008

⚠ **WARNING:** Cancer and Reproductive Harm – www.P65Warnings.ca.gov.

NIBCO[®]
AHEAD OF THE FLOW[®]

NIBCO INC.
WORLD HEADQUARTERS
WEB: www.nibco.com

1516 MIDDLEBURY STREET
ELKHART, IN 46516-4740
USA

DOMESTIC CUSTOMER SERVICE
PHONE: 800.234.0227
FAX: 800.234.0557

TECHNICAL SERVICE
PHONE: 888.446.4226
FAX: 888.336.4226

INTERNATIONAL OFFICE
PHONE: +1/574.295.3327
FAX: +1/574.295.3455