


1905 1/4" Ball Valve for Air Vent Isolation

MPT x FPT Threaded Ends - 1/4"

MATERIAL LIST	
PART	SPECIFICATION
Body	Brass - UNS C37700
Male Threaded End	Brass - UNS C37700
Seat	PTFE
Ball	Brass - UNS C37700
Stem	Brass - UNS C37700
Gland Seal	PTFE
Gland Nut	Brass - UNS C37700
Lever	Steel
Lever Retaining Nut	Steel
Stem Seal	PTFE

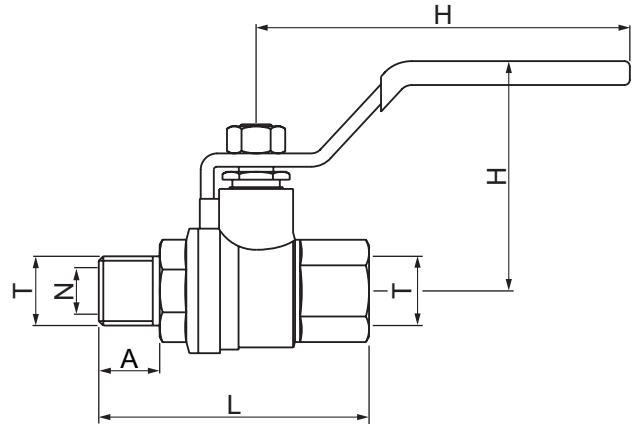

DIMENSIONS - In.							
Size	A	B	H	L	ØN	T - Thread	Weight Lbs.
1/4"	0.46	2.76	1.69	2.02	0.32	1/4" - 18 NPT	

600 PSI Non-Shock Cold Working Pressure to 160°F
Maximum Temperature 250°F @ 200 PSI

Project: _____

Contractor: _____

PO/Job No.: _____

Engineer: _____

Representative: _____

Date: _____