
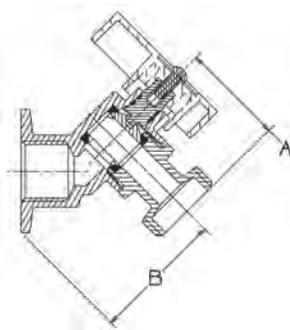


QTX Series Quarter-Turn Low Pressure Sillcocks

- IAPMO Listed to cUPC®



MATERIAL LIST

PART	SPECIFICATION
Screw	Steel
I.D. Tag	Aluminum
Handle	Zinc
Stem	Brass ASTM B 16 UNS C36000
O-Ring	Nitrile
Seat	PTFE
Ball	Brass ASTM B 16 UNS C36000
Adapter	Brass ASTM B 283 UNS C37700
Body	Brass ASTM B 283 UNS C37700

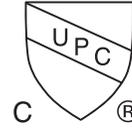


QT63X

DESCRIPTION	Nom. Size	DIMENSIONS		APPROX. NET WT.
		A	B	
ANGLE SILLCOCK Threaded to Hose	1/2	1.38"	1.77"	.44 lb
	3/4	1.38"	1.85"	.48 lb

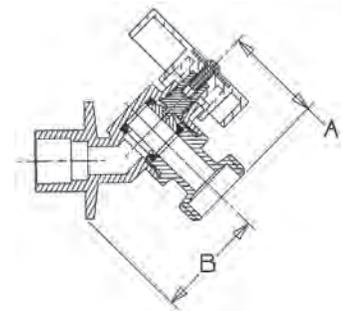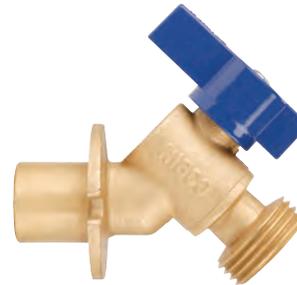

QT763IX

DESCRIPTION	Nom. Size	DIMENSIONS		APPROX. NET WT.
		A	B	
ANGLE SILLCOCK 1/2 Cup or 3/4 Ftg. to Hose	1/2 or 3/4	1.38"	1.57"	.50 lb

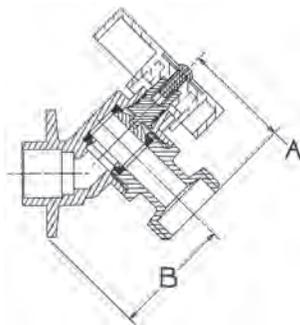

QT763X

DESCRIPTION	Nom. Size	DIMENSIONS		APPROX. NET WT.
		A	B	
ANGLE SILLCOCK Solder to Hose	1/2	1.38"	1.54"	.43 lb
	3/4	1.38"	1.69"	.48 lb

WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

NOT FOR USE WITH POTABLE DRINKING WATER APPLICATIONS AFTER JANUARY 3, 2014.